



MIL-DTL-5015 Type Reverse Bayonet or Threaded Coupling (Series IT and ITS) USB-A Memory Key

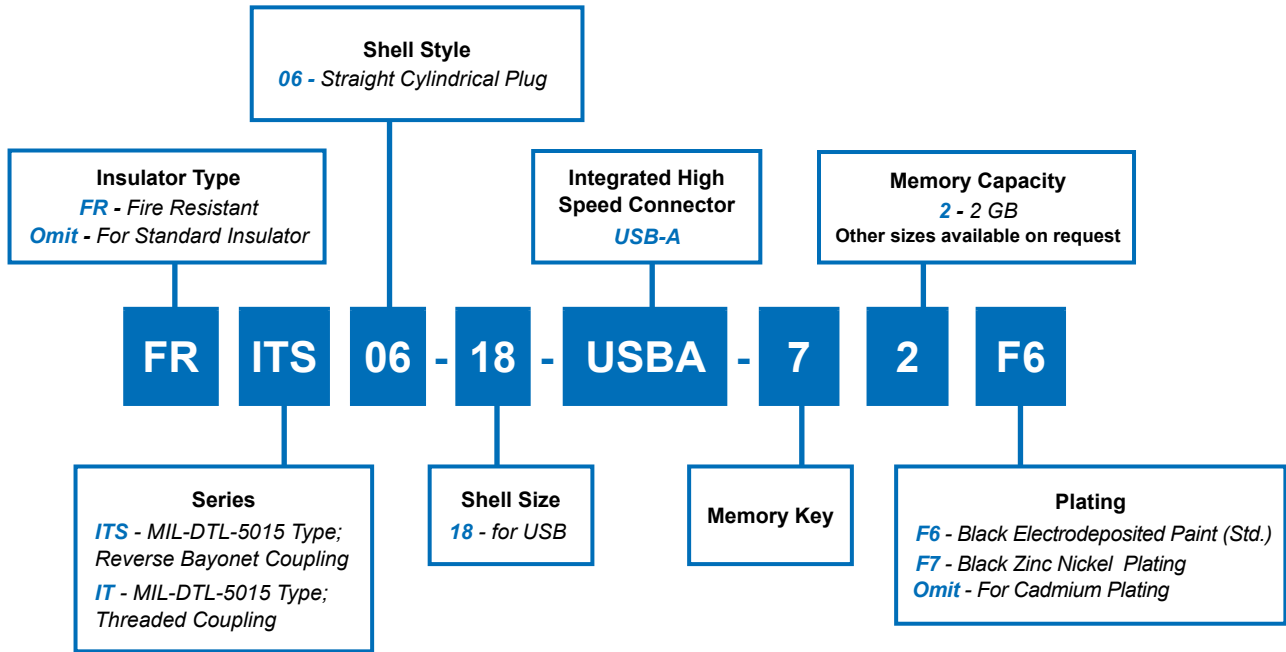


Figure 1  
ITS  
with USB-A Memory Key

# MIL-DTL-5015 Type Reverse Bayonet or Threaded Coupling (Series IT and ITS) USB-A Memory Key



Glenair combines the convenience of a USB-A memory key with the durability and environmental sealing of threaded or bayonet coupling MIL-DTL-5015 Type Connectors. Available in a robust aluminum shell with black electrodeposited paint or black zinc nickel plating, the Glenair USB-A memory key mates with your choice of IT or ITS type connectors with female USB-A contacts. Cadmium plating is also available.

Standard capacity: 2GB

TECHNICAL CHARACTERISTICS	
Inserts and Grommet	Suitable Rubber
Gaskets	Neoprene Rubber
Metallic Parts	Aluminum Alloy RoHS Compliant Finish Available
Contact	USB Type A Insert
Insulator	P.B.T UL 94-V0
Environmental Rating	IP67 (mated)
Memory Capability	2GB Standard *

\* (for other sizes available, please contact the factory)

