

RUGGEDIZED
RJ45 / USB
FIELD
CONNECTORS



SuperSeal RJ45 and USB field connectors. Now available for USB SuperSpeed 3.0



Military-grade, ruggedized field connectors that deliver improved environmental sealing, EMI/RFI grounding, and a broader range of wire termination options for RJ45 and USB—now for SuperSpeed 3.0

- New SuperSpeed USB 3.0 protocol support
- Superior sealing—IP67 unmated—for complete system protection against water, sand and dust
- Highly durable SuperSeal™ insert design, provides enhanced operating temperature, increased life-cycle, and rugged vibration and shock performance
- Crimp, solder-cup, PC tail and cable assemblies



Available ruggedized memory stick
32GB, 64GB, and 128GB versions

SuperSeal High-Speed Ruggedized RJ45/USB connectors and cables



SuperSpeed USB 3.0

NEW SUPERSPEED USB 3.0 RUGGEDIZED FIELD CONNECTORS



Cable plug

Wall mount receptacle with metric clinch nuts

Wall mount receptacle with slotted holes

Wall mount receptacle with round holes

Jam nut mount Receptacle


TURNKEY SUPERSPEED USB 3.0 CABLE ASSEMBLIES AND JUMPERS



Glenair SuperNine USB 3.0 cable jumpers, SuperSeal to standard USB Type A and Micro-B connectors

SuperSeal USB 3.0 connectors are available as turnkey cable jumpers. Rugged field connector styles—including plug, wall mount and jam-nut receptacles—may be cabled with commercial 3.0 connector types including male Type A, female Type A, and male Micro B. Assemblies may be ordered with straight or right angle cable exit. In addition, the USB 3.0 insert may be ordered in horizontal or vertical orientation to provide protection against mis-mating. Maximum overall length is 15 feet.

SUPPORTED USB 3.0 CONNECTOR TYPES

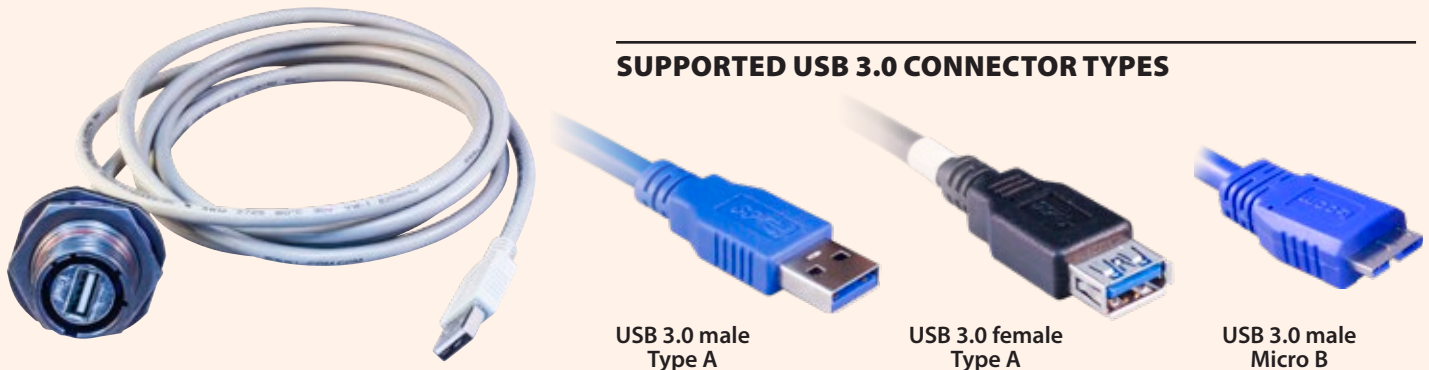


USB 3.0 male Type A

USB 3.0 female Type A

USB 3.0 male Micro B

USB ORIENTATION OPTIONS

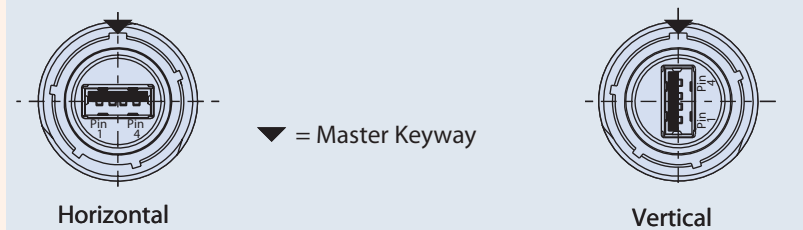

Horizontal

Vertical

SuperSeal High-Speed Ruggedized RJ45/USB connectors and cables

Available connector packaging



AVAILABLE TERMINATION OPTIONS



Solder Cup



PC tail



Crimp Contact



Jack-to-Jack



EMI Filtered



Quadrax



MIL-STD-1560 Arrangements



Turnkey Cordsets



SuperSeal™ MIL-DTL-38999 Series III Type RJ45 Connectors and Cordsets plus NEW Transient Voltage Suppression Solutions



SuperSeal™ MIL-DTL-Series 39999 Series III Type USB 2.0 Connectors and Cordsets



ITS SuperSeal™ (5015 Intermountable) Reverse-Bayonet RJ45 Connectors



ITS SuperSeal™ (5015 Intermountable) Reverse-Bayonet USB 2.0 Connectors


SuperSeal High-Speed Ruggedized RJ45/USB connectors and cables



Available connector packaging



IPT SuperSeal™ MIL-DTL-26482 Type Bayonet RJ45 Connectors

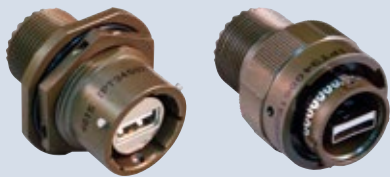

IPT SuperSeal™ MIL-DTL-26482 Type Bayonet USB Connectors



SuperSeal™ MIL-DTL-28840 Type RJ12/RJ45 and USB Shipboard Connectors



SuperSeal™ Series 801, 804 and 805 Mighty Mouse Micro USB 2.0 Connectors



SuperSeal™ Series 801, 804 and 805 Mighty Mouse RJ45 Connectors



SuperSeal™ Series 801, 804 and 805 Mighty Mouse Standard USB 2.0 Connectors