


SERIES 86

# SealTac Tactical Push-Pull Connectors

## 861-003 cable jumper high-speed HDMI

How To Order				
Sample Part Number	861-003-B	ZR	A	-36
Series	<b>861-003-A</b> = target contact push-pull plug-to-HDMI overmolded cable jumper <b>861-003-B</b> = spring contact push-pull receptacle-to-HDMI overmolded cable jumper			
Material / Finish	<b>ME</b> = Aluminum Electroless Nickel <b>ZR</b> = Aluminum / Black Zinc Nickel <b>Z1</b> = 316 Stainless Steel / Passivated			
Key Position	<b>A</b> = Normal <b>B</b> = Pos. B <b>C</b> = Pos. C <b>D</b> = Pos. D <b>E</b> = Pos. E <b>F</b> = Pos. F			
Cable Length	Cable length, "L" in inches, 114 inches max.			

MIGHTY MOUSE SEALTAC

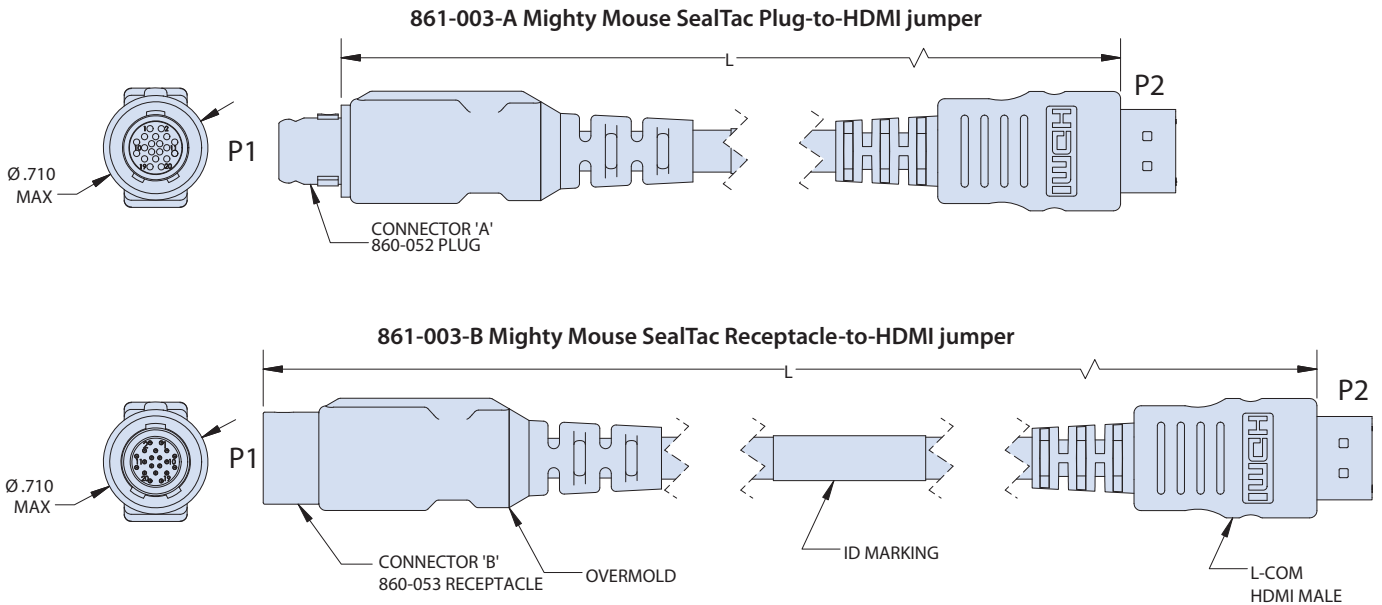

### MATERIAL / FINISH

- Connectors IAW 860-052 (plug) and 860-053 (receptacle)
- Overmold: TPV elastomer, black
- Cable: Low-smoke zero-halogen black jacket

### TECHNICAL SPECIFICATIONS

- Temperature range -10°C to +75°C
- 100% electrical testing, pin-pin and pin-shell DWV: 250 VAC min, IR = 10 MΩ min at 125 VDC, and continuity check