



# IPT-MB


No Dollar  
or Quantity  
Minimum Orders  
**NO  
MINS.**

## MIL-C-26482 High Density Connectors VG95328 Compliant Marine Bronze Series

**IPT-MB** connectors are the choice for reliability when 20-16 AWG signal cables are used. The insert arrangements as well as the electrical characteristics are detailed in the IPT IPT-SE Catalogue. Backshells suitable for EMI shield terminations and heat shrink boots are also available. The receptacle is also available with PCB contacts. IP67 protection is the standard performance. IP68 on request.

For further details and drawings about these connectors, and for a wider choice of backshell classes and connector shell styles, please refer to the related Glenair standard catalogue "IPT / IPT-SE Series Connectors"

### How To Order

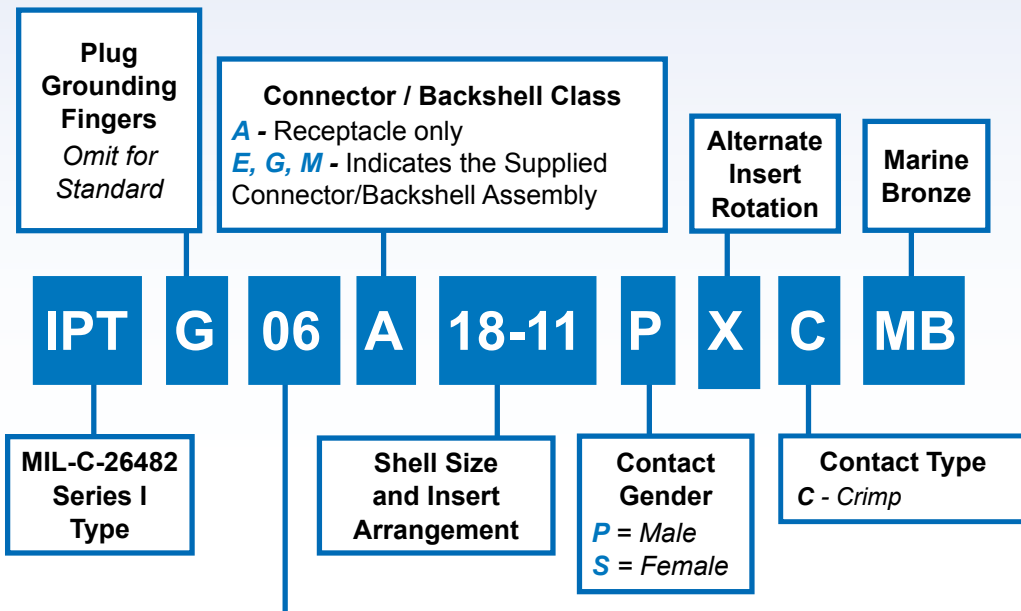

#### Connector Shell Styles

- 00 = Front Panel Mount Square Flange Receptacle with Accessory Threads
- 01 = In-Line Cylindrical Receptacle with Accessory Threads
- 02 = Front Panel Mount Square Flange Receptacle - No Accessory Threads
- 02PP = Solid Contact Bulkhead Feed Through
- 06 = Straight Cylindrical Plug Connector with Backshell
- 07 = Rear Panel Mount Jam Nut Receptacle - No Accessory Threads
- 070 = Rear Panel Mount Jam Nut Receptacle with Accessory Threads
- 08 = Cylindrical Plug Connector with 90° Backshell
- 26 = Square Flange Panel Mount Plug