

## ITB 07T-XX Jam Nut Connector Cap with Stainless Steel Chain

Basic Part Number and  
Shell Size Designator  
(Table I)

Length (in mm)  
Omit for Standard Length  
(Table I)


Material/Finish Options  
(Table II)

**ITB**

**07T-32**

**-XXX**

**XX**

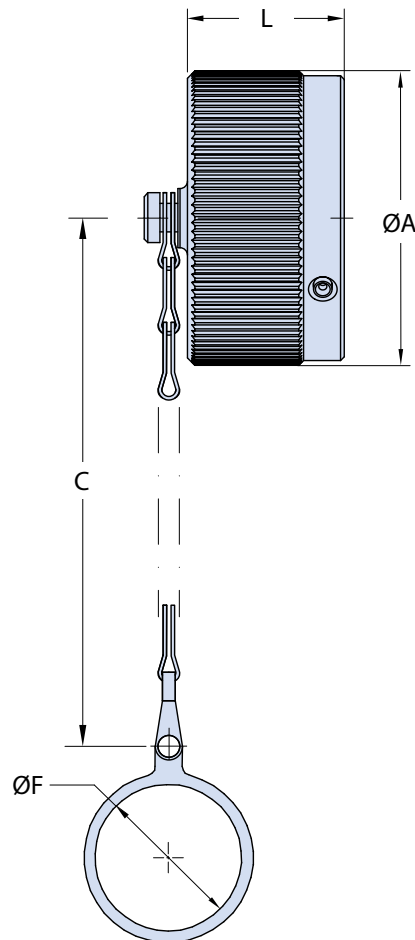

### Application Notes

1. Metal protective cap for bayonet receptacle connectors with stainless steel chain.
2. Standard materials configuration consists of aluminum alloy. For platings, see TABLE II finish options.

**ITB 07T-XX  
Jam Nut Connector Cap  
with Stainless Steel Chain**



**TABLE I: RECEPTACLE CONNECTOR CAP PART NUMBERS, CONNECTOR SIZE AND DIMENSIONS**

Part Number	Connector Size	ØA ±0.5	C Min.	ØF +0.2 -0.1	L Max.
<b>ITB 07T -10SL</b>	10SL	22.6	119	22.65	16.0
<b>ITB 07T -14</b>	14S	29.0	121	29.00	16.0
<b>ITB 07T -16</b>	16S	32.0	121	32.15	16.0
<b>ITB 07T -17</b>	16	32.0	137	32.15	21.0
<b>ITB 07T -18</b>	18	36.5	138	35.35	21.7
<b>ITB 07T -20</b>	20	39.8	138	38.50	21.7
<b>ITB 07T -22</b>	22	43.0	138	41.00	21.7
<b>ITB 07T -24</b>	24	46.4	138	44.70 (!)	21.7
<b>ITB 07T -28</b>	28	53.0	221	51.20 (!)	21.7
<b>ITB 07T -32</b>	32	60.0	221	57.50 (!)	21.7
<b>ITB 07T -36</b>	36	66.2	221	63.80 (!)	21.7
<b>ITB 07T -40</b>	40	72.3	221	70.20 (!)	21.7

(!) Please contact the factory.

**TABLE II**

STANDARD MATERIAL AND FINISH (*)		
Sym	Description	RoHS
	Omit for Aluminum/ Cadmium Olive Drab	
F6	Aluminum/ Black Electrodeposited Paint	✓
F7	Aluminum/ Black Zinc Nickel	✓
F11	Aluminum/ Electroless Nickel	✓
MB	Marine Bronze/ Unplated	✓
FK	Stainless Steel/ Passivate	✓

(\*) For further options, please contact the factory.